



此为证书 CN15/31713 译本

下述组织

安施新能源(成都)有限公司

注册地址: 中国四川省成都市青白江区工业集中发展区同旺路
866 号 5 栋 2 层
经营地址: 中国四川省成都市青白江区工业集中发展区同旺路
866 号 3 号厂房




的管理体系已经过审核, 并被证明符合下述要求

ISO 14001:2015

所涉及的活动范围覆盖

超级电容器的设计与制造

该证书的有效期自 2021 年 02 月 27 日至 2024 年 02 月 26 日
并须经过符合要求的监督审核保持有效
持续认证至少在证书失效前 60 天执行
版本号 3. 初始注册日期 2015 年 02 月 27 日

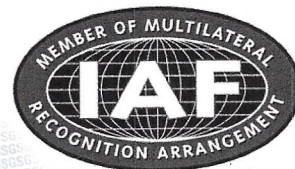

签署



0005

SGS United Kingdom Ltd
Rossmore Business Park Ellesmere Port Cheshire CH65 3 EN UK
t +44 (0)151 350-6666 f +44 (0)151 350-6600 www.sgs.com

HC SGS 14001 2015 0118

第 1 页 共 1 页



本文件由本公司根据公布在其网站 www.sgs.com/terms_and_conditions.htm
中的认证服务通用条款颁发。请注意其中已确定的责任范围、赔偿
和司法管辖事项。本文件的真实性可在网站
<https://www.sgs.com/en/certified-clients-and-products/certified-client-directory> 中核
实。任何未经授权的对此文件的内容或外观的变更、伪造或篡改均属
非法, 违反者将会被依法追诉。

Certificate CN15/31713

The management system of

AVX New Energy (Chengdu) Co., Ltd.

Business Registration Address: Floor 2, Building 5, No. 866 Tongwang Rd., Industrial Develop Zone, Qingbaijiang District, Chengdu City, Sichuan Province, P.R. China

Business Operation Address: Plant 3, No. 866 Tongwang Road, Industrial Develop Zone, Qingbaijiang District, Chengdu City, Sichuan Province, P.R. China



has been assessed and certified as meeting the requirements of

ISO 14001:2015

For the following activities

Design and manufacture of super capacitors

This certificate is valid from 27 February 2021 until 26 February 2024 and remains valid subject to satisfactory surveillance audits. Recertification audit due a minimum of 60 days before the expiration date Issue 3. Certified since 27 February 2015



Authorised by



0005

SGS United Kingdom Ltd
Rossmore Business Park Ellesmere Port Cheshire CH65 3EN UK
t +44 (0)151 350-6666 f +44 (0)151 350-6600 www.sgs.com

HC SGS 14001 2015 0118

Page 1 of 1



This document is issued by the Company subject to its General Conditions of Certification Services accessible at www.sgs.com/terms_and_conditions.html. Attention is drawn to the limitations of liability, indemnification and jurisdictional issues established therein. The authenticity of this document may be verified at <http://www.sgs.com/en/certified-clients-and-products/certified-client-directory>. Any unauthorized alteration, forgery or falsification of the content or appearance of this document is unlawful and offenders may be prosecuted to the fullest extent of the law.