



此为证书 CN20/21212 译本

下述组织

安施新能源（成都）有限公司

注册地址：中国四川成都市青白江区工业集中发展区同旺路
866号5栋2楼

经营地址：中国四川成都市青白江区工业集中发展区同旺路
866号3号厂房

统一社会信用代码 91510100MA62LOGH5J


的管理体系已经过审核，并被证明符合下述要求

ISO 9001:2015

所涉及的活动范围覆盖

超级电容器的设计与制造

该证书的有效期自 2020年 09月 22日至 2023年 09月 21日
组织必须定期接受监督审核并经审核合格此证书方继续有效
持续认证至少在证书失效前 60天执行
版本号 1. 初始注册日期 2020年 09月 22日

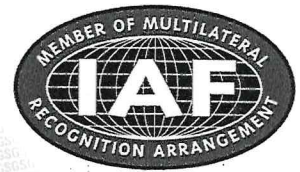

签署

SGS United Kingdom Ltd
Rossmore Business Park Ellesmere Port Cheshire CH65 3 EN UK
t +44 (0)151 350-6666 f +44 (0)151 350-6600 www.sgs.com
本证书信息可在国家认证认可监督管理委员会官方网站www.cnca.gov.cn上查询

HC SGS 9001 2015 0118

第1页 共1页



005



本文件由本公司根据公布在其网站 www.sgs.com/terms_and_conditions.htm 中的认证服务通用条款颁发。提请注意其中已确定的责任范围，赔偿和司法管辖事项。本文件的真实性可在网站 <https://www.sgs.com/en/certified-clients-and-products/certified-client-directory> 中核实。任何未经授权的对此文件的内容或外观的变更、伪造或篡改皆属非法，违反者将会被依法追究。

Certificate CN20/21212

The management system of

AVX New Energy (Chengdu) Co., Ltd.

Business Registration Address: 2nd Floor, Building 5th, No.866, Tongwang Rd., Industrial Development Zone, Qingbaijiang District, Chengdu City, Sichuan Province, P. R. China

Business Operation Address: 3rd, Building, No.866, Tongwang Rd., Industrial Development Zone, Qingbaijiang District, Chengdu City, Sichuan Province, P. R. China



Unified Social Credit Code 91510100MA62L0GH5J

has been assessed and certified as meeting the requirements of

ISO 9001:2015

For the following activities

Design and manufacture of super capacitors



This certificate is valid from 22 September 2020 until 21 September 2023 and remains valid subject to satisfactory surveillance audits. Recertification audit due a minimum of 60 days before the expiration date. Issue 1. Certified since 22 September 2020

Authorised by

SGS United Kingdom Ltd
Rossmore Business Park, Ellesmere Port, Cheshire, CH65 3EN, UK
t: +44 (0)151 350-6966 f: +44 (0)151 350-6600 www.sgs.com
The certification information can be verified on the web site of Certification and Accreditation Administration of the People's Republic of China www.cca.gov.cn

HC SGS 9001 2015 0118



This document is issued by the Company subject to its General Conditions of Certification Services accessible at www.sgs.com/terms_and_conditions.htm. Attention is drawn to the limitations of liability, indemnification and jurisdictional issues established therein. The authenticity of this document may be verified at <http://www.sgs.com/en/certified-clients-and-products/certified-client-directory>. Any unauthorized alteration, forgery or falsification of the content or appearance of this document is unlawful and offenders may be prosecuted to the fullest extent of the law.